



GE
Lighting

23830 - Q1500T3/CL

GE halogen 1500 watt T3 1-pack

- 240 volts
- GE halogen bulbs deliver crisp, white light. This unsurpassed light quality is ideal for adding depth, drama and interest to any room or space. Use GE halogen specialty bulbs to create a dramatic effect
- Lasts 1.8 years based on 3 hours per day usage
- T3 shape with Recessed Single Contact (R7s) base for use in outdoor carriage and post lights



GENERAL CHARACTERISTICS

Lamp Type	Halogen - Single-Ended
Bulb	T3
Base	Recessed Single Contact (R7s)
Filament	C-8
Rated Life	2000.0 hrs

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	32000.0
Color Temperature	3050.0 K
Nominal Initial Lumens per Watt	21

ELECTRICAL CHARACTERISTICS


Wattage	1500.0
Voltage	240.0
Burn Position	Horizontal

DIMENSIONS

Maximum Overall Length (MOL)	10.0630 in(255.6 mm)
Bulb Diameter (DIA)	0.375 in(9.5 mm)
Light Center Length (LCL)	6.313 in(160.4 mm)

PRODUCT INFORMATION

Product Code	23830
Description	Q1500T3/CL
Standard Package	Case
Standard Package GTIN	10043168238301
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168238304

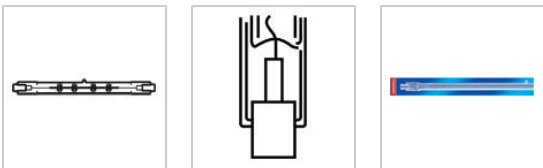

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.

Warning

- Lamp emits UV radiation which may cause eye/skin injury. RG-3
 - Avoid exposure of eyes and skin to unshielded lamp.
- Risk of Electric Shock
 - Turn power off before inspection, installation or removal.
- Risk of Burn
 - Allow lamp to cool before handling.
 - Turn power off before installing lamp.
- Risk of Fire
 - Fire Hazard! Do not use in Torchieres or other indoor residential fixtures.
 - Keep combustible materials away from lamp.
 - Use in enclosed fixture rated for this product.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Do not exceed 110% of rated voltage.
 - Do not touch glass with bare hands.
 - Do not use lamp if outer glass is scratched or broken.
 - Operate lamp only in specified position -- see instructions.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.




GE
Lighting

23830 - Q1500T3/CL

GE halogen 1500 watt T3 1-pack

- 240 volts
- GE halogen bulbs deliver crisp, white light. This unsurpassed light quality is ideal for adding depth, drama and interest to any room or space. Use GE halogen specialty bulbs to create a dramatic effect
- Lasts 1.8 years based on 3 hours per day usage
- T3 shape with Recessed Single Contact (R7s) base for use in outdoor carriage and post lights

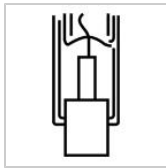

GENERAL CHARACTERISTICS

Lamp Type	Halogen - Single-Ended
Bulb	T3
Base	Recessed Single Contact (R7s)
Filament	C-8
Rated Life	2000.0 hrs

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	32000.0
Color Temperature	3050.0 K
Nominal Initial Lumens per Watt	21

ELECTRICAL CHARACTERISTICS

Wattage	1500.0
Voltage	240.0
Burn Position	Horizontal

DIMENSIONS

Maximum Overall Length (MOL)	10.0630 in(255.6 mm)
Bulb Diameter (DIA)	0.375 in(9.5 mm)
Light Center Length (LCL)	6.313 in(160.4 mm)

PRODUCT INFORMATION

Product Code	23830
Description	Q1500T3/CL
Standard Package	Case
Standard Package GTIN	10043168238301
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168238304

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.

Warning

- Lamp emits UV radiation which may cause eye/skin injury. RG-3
 - Avoid exposure of eyes and skin to unshielded lamp.
- Risk of Electric Shock
 - Turn power off before inspection, installation or removal.
- Risk of Burn
 - Allow lamp to cool before handling.
 - Turn power off before installing lamp.
- Risk of Fire
 - Fire Hazard! Do not use in Torchieres or other indoor residential fixtures.
 - Keep combustible materials away from lamp.
 - Use in enclosed fixture rated for this product.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Do not exceed 110% of rated voltage.
 - Do not touch glass with bare hands.
 - Do not use lamp if outer glass is scratched or broken.
 - Operate lamp only in specified position -- see instructions.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.