




GE
Lighting

20814 - Q20MR16C/FL40 10

GE ConstantColor® Precise™ MR16

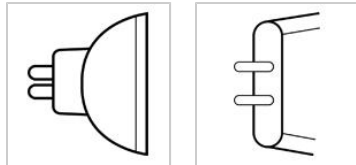

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.

Warning

- Risk of Burn
 - Allow lamp/fixture to cool before handling.
 - Turn power off before installing lamp.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in enclosed fixture rated for this product-- see instructions.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Do not touch glass with bare hands.
 - Do not use lamp if outer glass is scratched or broken.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.

GENERAL CHARACTERISTICS

Lamp Type	Halogen - MR
Bulb	MR16
Base	2-Pin (GX5.3)
Filament	C-6
Rated Life	5000.0 hrs
Lamp Enclosure Type (LET)	Open or enclosed fixtures

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	240.0
Center Beam Candlepower (CBCP)	525.0
Color Temperature	2900.0 K
Beam Spread	40.0 °

ELECTRICAL CHARACTERISTICS

Wattage	20.0
Voltage	12.0

DIMENSIONS

Maximum Overall Length (MOL)	1.8750 in(47.6 mm)
Bulb Diameter (DIA)	2.000 in(50.8 mm)

PRODUCT INFORMATION

Product Code	20814
Description	Q20MR16C/FL40 10
ANSI Code	BAB
Standard Package	BUNDLE
Standard Package GTIN	00043168208147
Standard Package Quantity	20
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	20
UPC	043168990080



GE
Lighting

20814 - Q20MR16C/FL40 10

GE ConstantColor® Precise™ MR16



GENERAL CHARACTERISTICS

Lamp Type	Halogen - MR
Bulb	MR16
Base	2-Pin (GX5.3)
Filament	C-6
Rated Life	5000.0 hrs
Lamp Enclosure Type (LET)	Open or enclosed fixtures

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	240.0
Center Beam Candlepower (CBCP)	525.0
Color Temperature	2900.0 K
Beam Spread	40.0 °

ELECTRICAL CHARACTERISTICS


Wattage	20.0
Voltage	12.0

DIMENSIONS

Maximum Overall Length (MOL)	1.8750 in(47.6 mm)
Bulb Diameter (DIA)	2.000 in(50.8 mm)

PRODUCT INFORMATION

Product Code	20814
Description	Q20MR16C/FL40 10
ANSI Code	BAB
Standard Package	BUNDLE
Standard Package GTIN	00043168208147
Standard Package Quantity	20
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	20
UPC	043168990080

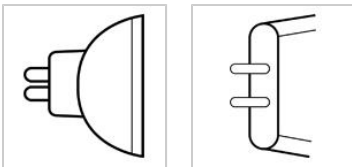

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.

Warning

- Risk of Burn
 - Allow lamp/fixture to cool before handling.
 - Turn power off before installing lamp.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in enclosed fixture rated for this product-- see instructions.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Do not touch glass with bare hands.
 - Do not use lamp if outer glass is scratched or broken.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.