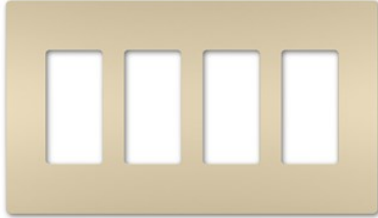


---

## FOUR-GANG SCREWLESS WALL PLATE, IVORY

RWP264I | [radiant](#)

---

### FEATURES & BENEFITS

A step above the standard with no unsightly screws, this modern, low-profile wall plate instantly elevates the look of radiant dimmers, switches, outlets, home automation controls and more.

Available in White, Ivory, Light Almond, Black, Brown and Gray, as well as three metallic finishes: Nickel, Dark Bronze and Antique Brass (all sold separately) to coordinate with most any decor.

- **Redesigned screwless wall plates** feature a lower, more modern profile in keeping with today's design trends.
- **Molded of rugged .065" thick polycarbonate**
- **One-piece subplate** mounts over the device for easy retrofit and lower profile.
- **Subplate screws align devices** to ensure proper positioning of the wall plate.
- **Opening accommodates all NEMA 26-opening devices.**
- **An extra 3/8" width and height than standard size wall plates** for more tolerance in covering ragged sheet rock openings.

---

### SPECIFICATIONS

#### GENERAL INFO

Color: Ivory  
Special Features: Screwless

#### CONSTRUCTION INFORMATION

Component 4: 78500729576

#### DIMENSIONS

Height (US): 4.94"  
Width (US): 8.59"

#### TECHNICAL INFORMATION

Material: Polycarbonate


#### BUY AMERICAN ACT COMPLIANCE

Country Of Origin: UNITED STATES OF AMERICA  
Buy American Act Status: Buy American Act Compliant



---

## FOUR-GANG SCREWLESS WALL PLATE, IVORY

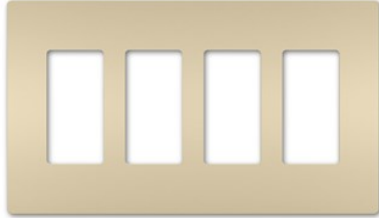RWP264I | [radiant](#)

---

### FEATURES & BENEFITS

A step above the standard with no unsightly screws, this modern, low-profile wall plate instantly elevates the look of radiant dimmers, switches, outlets, home automation controls and more.

Available in White, Ivory, Light Almond, Black, Brown and Gray, as well as three metallic finishes: Nickel, Dark Bronze and Antique Brass (all sold separately) to coordinate with most any decor.

- **Redesigned screwless wall plates** feature a lower, more modern profile in keeping with today's design trends.
- **Molded of rugged .065" thick polycarbonate**
- **One-piece subplate** mounts over the device for easy retrofit and lower profile.
- **Subplate screws align devices** to ensure proper positioning of the wall plate.
- **Opening accommodates all NEMA 26-opening devices.**
- **An extra 3/8" width and height than standard size wall plates** for more tolerance in covering ragged sheet rock openings.

---

### SPECIFICATIONS

#### GENERAL INFO

Color: Ivory  
Special Features: Screwless

#### CONSTRUCTION INFORMATION

Component 4: 78500729576

#### DIMENSIONS

Height (US): 4.94"  
Width (US): 8.59"

#### TECHNICAL INFORMATION

Material: Polycarbonate

BUY AMERICAN ACT COMPLIANCE

Country Of Origin: UNITED STATES OF AMERICA  
Buy American Act Status: Buy American Act Compliant

