




# S2414

40ST19/CL /9S /120V /Vintage  
40 watt ST19 Incandescent; Clear; 3000 average rated hours;  
160 lumens; Medium base; 120 volts

### Features

- Vintage Style incandescent
- Historic restoration quality
- Classic, warm glow

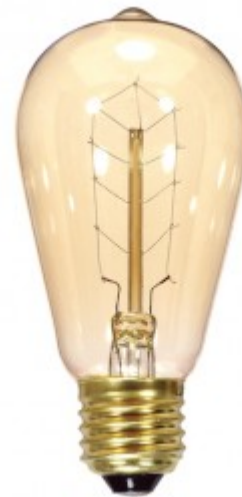

S2414

| Item Number | UPC          | Watts | Lamp Shape | Base   | ANSI Base | Lamp Code                    | Voltage |
|-------------|--------------|-------|------------|--------|-----------|------------------------------|---------|
| S2414       | 045923024146 | 40    | ST19       | Medium | E26       | 40ST19/CL /9S /120V /Vintage | 120     |

| Finish | MOL In Inches | MOD In Inches | Filament | Initial Lumens | Average Rated Hours | Pack | Package Type |
|--------|---------------|---------------|----------|----------------|---------------------|------|--------------|
| Clear  | 5 3/16"       | 2.38"         | Hairpin  | 160            | 3000                | 48/6 | Box          |

| RoHS Compliant |
|----------------|
| Yes            |



National Toll-Free:  
800.43.SATCO  
(800.437.2826)  
www.satco.com

Distribution Centers:  
New York, Florida, Texas,  
Washington, California,  
Puerto Rico

Corporate Offices:  
110 Heartland Blvd.,  
Brentwood, NY 11717  
800.437.2826 631.243.2022  
Fax 631.243.2027






# S2414

40ST19/CL /9S /120V /Vintage  
40 watt ST19 Incandescent; Clear; 3000 average rated hours;  
160 lumens; Medium base; 120 volts

### Features

- Vintage Style incandescent
- Historic restoration quality
- Classic, warm glow

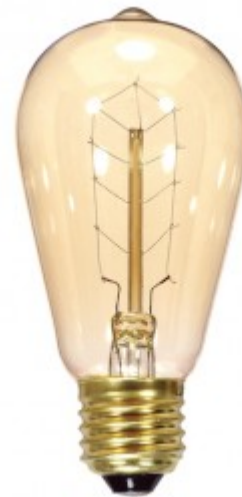

S2414

| Item Number | UPC          | Watts | Lamp Shape | Base   | ANSI Base | Lamp Code                    | Voltage |
|-------------|--------------|-------|------------|--------|-----------|------------------------------|---------|
| S2414       | 045923024146 | 40    | ST19       | Medium | E26       | 40ST19/CL /9S /120V /Vintage | 120     |

| Finish | MOL In Inches | MOD In Inches | Filament | Initial Lumens | Average Rated Hours | Pack | Package Type |
|--------|---------------|---------------|----------|----------------|---------------------|------|--------------|
| Clear  | 5 3/16"       | 2.38"         | Hairpin  | 160            | 3000                | 48/6 | Box          |

| RoHS Compliant |
|----------------|
| Yes            |



National Toll-Free:  
800.43.SATCO  
(800.437.2826)  
www.satco.com

Distribution Centers:  
New York, Florida, Texas,  
Washington, California,  
Puerto Rico

Corporate Offices:  
110 Heartland Blvd.,  
Brentwood, NY 11717  
800.437.2826 631.243.2022  
Fax 631.243.2027

