



SCH1 SINGLE PIECE STRUT CLAMP FOR CONDUIT, 0.34"–0.71" OD, 1/2" EMT

CATALOG NUMBER

SCH8



CERTIFICATIONS



FEATURES

One-piece conduit clamp

No screws or bolts to drop

Requires only a screwdriver or nutdriver for installation

Fits into open side of strut channel

PRODUCT ATTRIBUTES

Material: Steel


Finish: Electrogalvanized

Outer Diameter (OD): 0.340" - 0.71"

EMT Conduit Size: 1/2"

Static Load (F): 200lb

DIAGRAMS

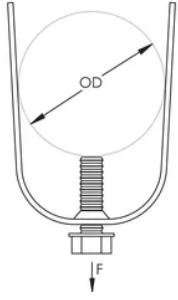

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER



SCH1 SINGLE PIECE STRUT CLAMP FOR CONDUIT, 0.34"–0.71" OD, 1/2" EMT

CATALOG NUMBER

SCH8



CERTIFICATIONS



FEATURES

One-piece conduit clamp

No screws or bolts to drop

Requires only a screwdriver or nutdriver for installation

Fits into open side of strut channel

PRODUCT ATTRIBUTES

Material: Steel


Finish: Electrogalvanized

Outer Diameter (OD): 0.340" - 0.71"

EMT Conduit Size: 1/2"

Static Load (F): 200lb

DIAGRAMS

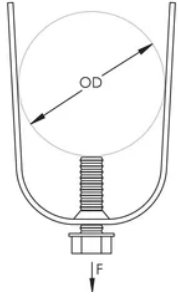

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY** **ERICO** **HOFFMAN** **RAYCHEM** **SCHROFF**
TRACER