

Wall Plates & Specialties



Pass & Seymour

Molded of rugged .065" thick polycarbonate.

An extra 1/8" width and height than standard size wall plates for more tolerance in covering ragged sheet rock openings.

Seamless, sleek, super smooth construction provides no dirt-catching channel around plate's perimeter.

Oversized opening to accommodate all NEMA 26 decorator-style openings.

SWP26W

Automatic alignment pins ensure that devices are properly positioned so that wall plates fit perfectly.

Two-piece plastic subplate bridges recessed boxes and uneven sheet rock. Fixes floating installations.



Style	Page Number
Specifications & Dimensions	Q-2 – Q-4
Screwless Wall Plates	Q-5, Q-6
Studio Wall Plates	Q-7
Toggle Switch Openings	Q-8
Duplex Receptacle Openings & Decorator Openings	Q-9
Decorator Openings	Q-10
Blank Plates	Q-11, Q-12
Single Receptacle Openings & Power Outlet Openings	Q-13, Q-14
Combination Openings	Q-15 – Q-18
Despard® Openings	Q-19
Two Gang with Center Opening & Locking Switch Plates	Q-20
Louver & Biplex/Triplex Openings	Q-21
Junior-Jumbo & Jumbo Toggle, Duplex, Single Receptacle, Decorator, Blank & Combination Openings	Q-22 – Q-24
Sectional Wall Plates	Q-25
Tandem & Handy Box Plates	Q-26
Narrow Metal	Q-27
Dustproof Stainless Steel Covers	Q-28
Communication Devices & Plates	Q-29 – Q-34
Mounting Straps, Yokes & Jewels	Q-35
Decorator Hallway Lights & Combination Devices	Q-36
Decorator Combination Tamper-Resistant Nightlight/GFCI Receptacles	Q-37
PlugTail™ Nightlight/GFCI Receptacles	Q-38
Incandescent Lampholders, Neon Pilot Lights & Panelites	Q-39
Screws & Screwdrivers	Q-40
Engraved & Pad Printed	Q-41, Q-42
Custom Metal Wall Plates	Q-43 – Q-45
Custom Panel Plates	Q-46, Q-47
Style Selector Guide	Q-48 – Q-60

Devices & Wall Plates Color Selection Chart available on Pages A-29, B-78 and Q-61.



Pass & Seymour

Thermoset
SP SeriesNylon
TP SeriesStudio
Polycarbonate
WP SeriesScrewless
Polycarbonate
SWP Series

Wall Plates Specifications

Application

Legrand/Pass & Seymour's broad line of Standard Size Plastic and Metal Wall Plates features the most complete range of types, sizes, colors, and finishes available. Choose from more than 1,900 standard plates in non-combustible thermoset plastic material, self-extinguishing nylon material, screwless polycarbonate material, or attractively finished metal, for residential, commercial, institutional, and industrial applications. All plastic wall plates color match to Legrand/Pass & Seymour devices.

Thermoset Plastic Wall Plates

- Molded of non-combustible mar-proof material.
- Available in "SP" series in Standard, Junior-Jumbo, and Jumbo sizes.
- Seven standard colors available – Ivory, White, Brown, Gray, Black, Red, and Light Almond.
- Individually wrapped with color-matching screws.
- Resistant to discoloration, grease, oil, solvent and moisture.
- Nominal thickness, .070"

TradeMaster® Thermoplastic Wall Plates

- Molded of rugged, practically indestructible self-extinguishing nylon. ("TP" series only.)
- Available in "TP" series, extra 3/16" width and height than Standard size plates; and "TPJ" series, extra 3/16" width and height than Junior-Jumbo size plates.
- Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.
- Preferred for hospital, industrial, institutional, and other high-abuse applications.
- Nominal thickness, .070"

Studio Polycarbonate Wall Plates

- Wall plate and back plate made of polycarbonate Lexan 241R opaque.
- Wall plate thickness: 0.210
Back plate thickness: 0.28

Screwless Polycarbonate Wall Plates

- Molded of .065" thick polycarbonate, matte finish.
- 2-piece plastic subplate made of polycarbonate.
- Extra 1/8" width and height than Standard size plates.
- Available in Ivory, White, Brown, Gray, Black, and Light Almond; and five metallic and three wood finishes.

Metal Wall Plates


- Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze or galvanized steel.
- Standard, Jumbo, and Tandem size plates available, as well as special Panel size plates up to 5-gangs high and 10-gangs wide.
- Packaged in protective film, with finish-matching screws.
- Variety of special plated finishes. Paintable to match plastic plates.
- Can be silk-screened or engraved, and custom punched with over 300 opening styles.

Materials

- Type 302 Stainless Steel, non-magnetic, .032" nominal thickness, brushed finish. This alloy contains 18% chromium and 8% nickel for superior resistance to corrosion. Recommended for use in food processing plants, dairies, chemical plants, and other industrial, institutional, and commercial applications where corrosive atmospheres exist.
- Type 430 Stainless Steel, magnetic, .032" nominal thickness, brushed finish. Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and institutional buildings.
- Chrome, Brushed and Polished Brass, .040" thick. 70% copper, 30% zinc alloy gives warm, appealing finish to modern decor as well as retrofit applications. Lacquered to prevent corrosion.
- Aluminum, .040" thick. Lustrous satin finish. Lacquered to prevent corrosion.
- Galvanized Steel. Used only for Handy Box Plates.
- Brushed Bronze, .040" thick. 90% copper, 10% zinc. Lacquered to prevent corrosion.

302
Stainless Steel

Polished Brass

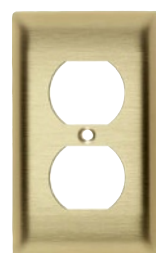

Brushed Brass




Aluminum

Wall Plates Dimensions




Pass & Seymour

Standard Size Wall Plates					
■ Standard size wall plates for all applications.			■ Available in plastic and metal only.		
■ Best fit for surface mount boxes.					
Dimensions					
1 gang	2.75" x 4.5"	4 gang	8.125" x 4.5"	7 gang	13.62" x 4.5"
2 gang	4.56" x 4.5"	5 gang	10" x 4.5"	8 gang	15.44" x 4.5"
3 gang	6.375" x 4.5"	6 gang	11.812" x 4.5"		

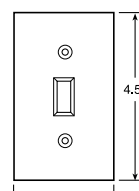


STANDARD

TradeMaster® Wall Plates					
<ul style="list-style-type: none">■ Extra 3/16" width and height than Standard size wall plates.■ Provide better sheet rock coverage with standard size appearance.■ Available in unbreakable nylon 6 construction only.■ Screws pre-installed in the duplex, toggle, and decorator single gang plates.					
Dimensions					
1 gang	2.9375" x 4.6875"	3 gang	6.563" x 4.6875"	5 gang	10.188" x 4.6875"
2 gang	4.75" x 4.6875"	4 gang	8.375" x 4.6875"	6 gang	12" x 4.6875"

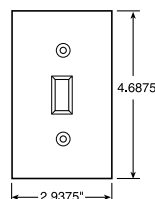

TRADEMASTER STANDARD


Studio Polycarbonate Wall Plates					
<ul style="list-style-type: none"> Wall plate and back plate made of polycarbonate Lexan 241R opaque. 			<ul style="list-style-type: none"> Wall plate thickness: 0.210 Back plate thickness: 0.28 		
Wall Plate Dimensions			Back Plate Dimensions		
1 gang	2.988" x 4.901"	3 gang	6.613" x 4.901"	1 gang	3.158" x 4.97"
2 gang	4.80" x 4.901"	4 gang	8.425" x 4.901"	3 gang	6.783" x 4.97"
				2 gang	4.97" x 4.97"
				4 gang	8.595" x 4.97"

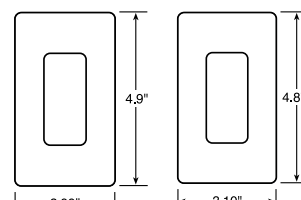

STUDIO


SCREWLESS

Screwless Polycarbonate Wall Plates					
<ul style="list-style-type: none"> Available in decorator, toggle, and duplex openings. Extra 1/8" width and height than Standard size wall plates. Provide better sheet rock coverage with standard size appearance. Molded of .065" thick polycarbonate. 2-piece plastic subplate made of polycarbonate. Available in five metallic and three wood finishes; and six standard colors. 					
Wall Plate Dimensions			Subplate Dimensions		
1 gang	3.10" x 4.87"	3 gang	6.724" x 4.87"	1 gang	2.85" x 4.62"
2 gang	4.912" x 4.87"	4 gang	8.536" x 4.87"	3 gang	6.474" x 4.62"
				2 gang	4.662" x 4.62"
				4 gang	8.286" x 4.62"

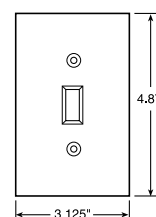

JUNIOR-JUMBO


Junior-Jumbo Wall Plates					
<div>■ Extra 3/8" width and height than Standard size wall plates.</div> <div>■ Additional coverage for sheet rock gaps.</div>			<div>■ Available in plastic and metal only.</div>		
Dimensions					
1 gang	3.125" x 4.87"	2 gang	4.93" x 4.87"	3 gang	6.75" x 4.87"
		4 gang	8.56" x 4.87"		

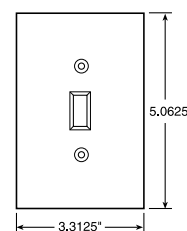

TRADEMASTER JUMBO

TradeMaster Jumbo Wall Plates			
<ul style="list-style-type: none">■ Extra 3/16" width and height than Junior-Jumbo size wall plates.■ Provide additional coverage for sheet rock gaps, matching the appearance of the TradeMaster Plates.■ Available in unbreakable nylon 6 construction only.■ Screws pre-installed in the duplex, toggle, and decorator single gang plates.			
Dimensions			
1 gang	3.3125" x 5.0625"	3 gang	6.9375" x 5.0625"
2 gang	5.125" x 5.0625"	4 gang	8.75" x 5.0625"

Jumbo Wall Plates							
<ul style="list-style-type: none">■ Extra 3/4" width and height than Standard size wall plates.■ Largest size wall plates to cover larger wall damage.				<ul style="list-style-type: none">■ Available in plastic and metal only.			
Dimensions							
1 gang	3.5" x 5.25"	2 gang	5.31" x 5.25"	3 gang	7.12" x 5.25"	4 gang	8.93" x 5.25"

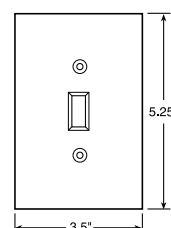


JUMBO



Pass & Seymour

Wall Plates Dimensions




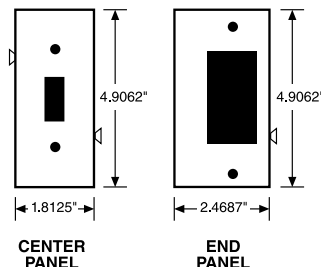


Sectional Wall Plates







- End and center panels with each of five most-used configurations make it possible to improvise custom wall plates on the job. Panels lock securely together on installation. Blank sections furnished with mounting strap.

Wall Plate Mountings

Illustrated are the five standard methods of plate mounting. There are many other non-standard methods which depend upon the special device used. Exact mounting hole specifications for every device appear in the Selector Guide.

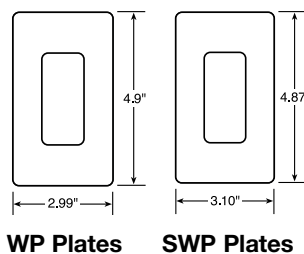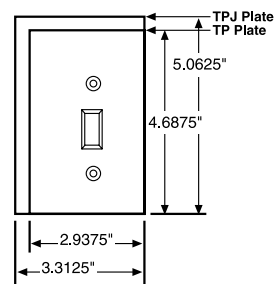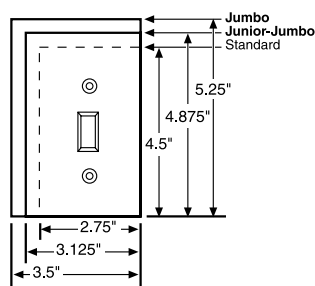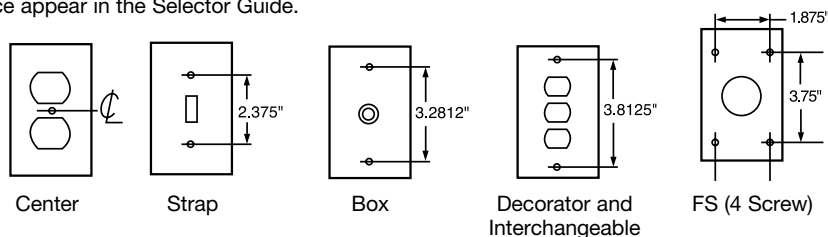


Wall Plate Sizes

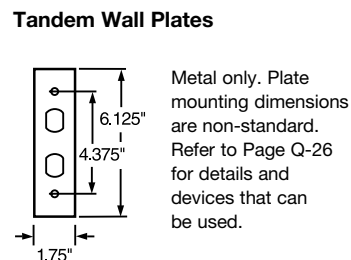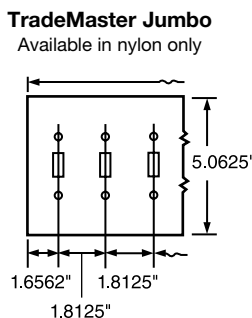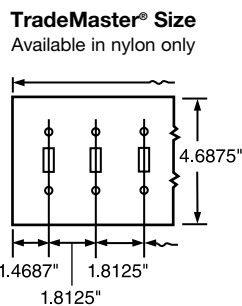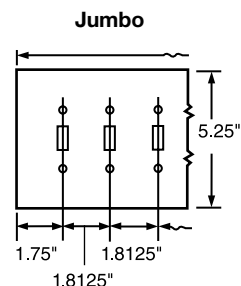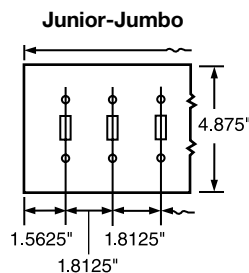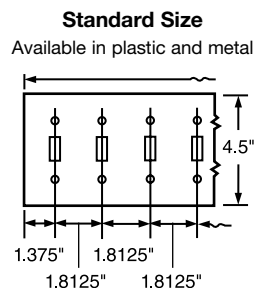

For Studio (WP) Wall Plate & Back Plate dimensions refer to Page Q-3.

Screwless Wall Plate Plastic Subplate

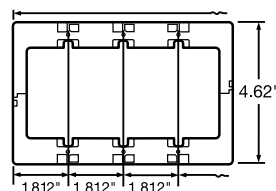



 





 
 






For Screwless (SWP) Wall Plate dimensions refer to Page Q-3.

Wall Plates Narrow Metal

Made to Order – Consult factory for price and availability



Pass & Seymour

Made to Order Wall Plates							
Description	Material	Catalog Numbers					
 Toggle Switch	Aluminum 302S/S	SAN11 SSN11			SAN14 SSN14	SSN15	
 Telephone Outlet 13/32" Hole – Box Mounted	302S/S						SSN117
 Telephone Outlet 13/32" Hole – Strap Mounted	302S/S	SSN121					
 Blank Strap Mounted, 1 #340 Yoke	Aluminum 302S/S		SSN142		SAN144 SSN144		
 Duplex Receptacle	Aluminum 302S/S					SAN85 SSN85	
 1 Despard® Interchangeable Horizontal Opening Supplied With #348 Mounting Strap	Aluminum 302S/S				SANK14 SSNK14		
 2 Despard Interchangeable Horizontal Openings Supplied With #348 Mounting Strap	Aluminum 302S/S				SANK24 SSNK24		
 3 Despard Interchangeable Horizontal Openings Supplied With #348 Mounting Strap	302S/S				SSNK34		
 1 Despard Interchangeable Vertical Opening Supplied With #347 Mounting Strap	Aluminum 302S/S	SANK41 SSNK41		SANK43 SSNK43	SANK44 SSNK44		
 1 Despard Interchangeable Vertical Opening Device Mounted Use with #347 Strap	Aluminum 302S/S	SANK51 SSNK51		SANK53 SSNK53	SANK54 SSNK54		


Note: All narrow plates are 4-1/2" high.

Devices & Wall Plates Color Selection Chart




Pass & Seymour

Devices & Plastic Wall Plate Colors

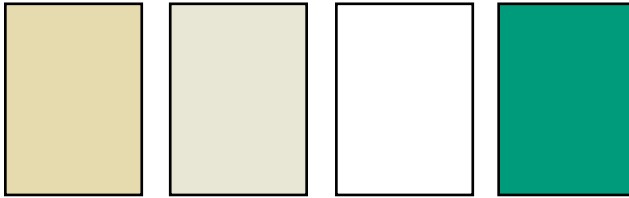


Ivory Light Almond White Green

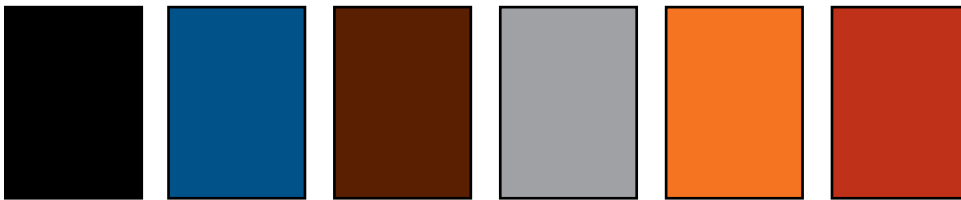

Black Blue Brown Gray Orange Red


See specific device and wall plate catalog charts for particular color availabilities.

Metal Wall Plates

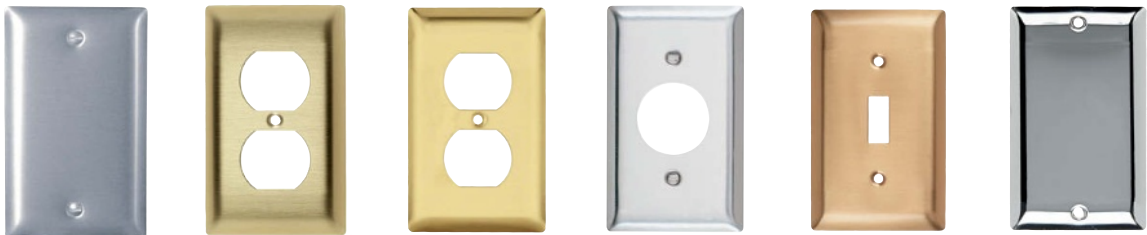


Metal Finish Aluminum Brass (Brushed) Polished Brass Stainless Steel Brushed Bronze Chrome

Custom Metal Wall Plates Paint Finish Colors

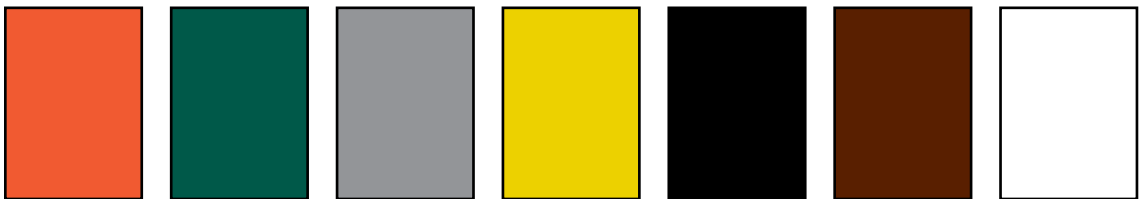

Paint Color Orange Green Gray Yellow Glossy Black Brown White

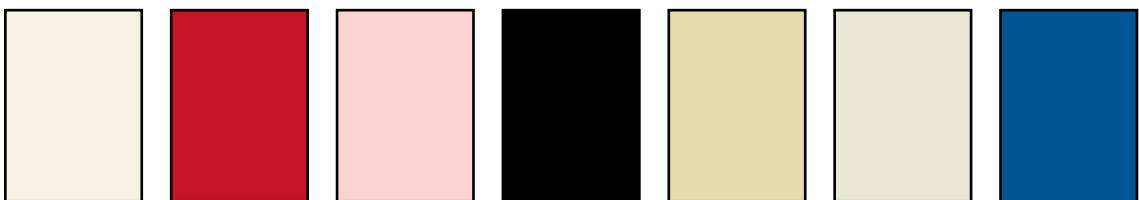

Paint Color Primer Red Pink Flat Black Ivory Light Almond Blue

To order custom metal wall plates, see Pages Q-43 – Q-45.

For additional colors consult factory.