

## INSPECTION HOUSING, HIGH DENSITY POLYETHYLENE (HDPE), 13.1" OD, 10"

### CATALOG NUMBER

**T416B**



### FEATURES

Pedestrian load rating

Suitable for lighter load rating applications in turf

Chemical, UV and corrosion resistant

3/8" x 2 1/2" (64 mm) stainless steel lock bolt included

Boxes and covers nest in 3 1/4" (83 mm) increments

Two 3 1/2" x 1 1/2" (89 x 38 mm) knockouts per box

T416BH includes four additional holes in the cover to allow water to enter the inspection well, typically for use with chemical ground rods

### PRODUCT ATTRIBUTES

Material: High Density Polyethylene (HDPE)

Color: Green

Load Rating: 300lb/ft<sup>2</sup>

Diameter, Grade Level (DG): 10 1/4"


Outer Diameter (OD): 13.1"

Height (H): 10"

Unit Weight: 4.5 lb

## DIAGRAMS

---

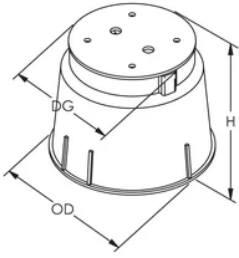

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**

## INSPECTION HOUSING, HIGH DENSITY POLYETHYLENE (HDPE), 13.1" OD, 10"

### CATALOG NUMBER

**T416B**



### FEATURES

Pedestrian load rating

Suitable for lighter load rating applications in turf

Chemical, UV and corrosion resistant

3/8" x 2 1/2" (64 mm) stainless steel lock bolt included

Boxes and covers nest in 3 1/4" (83 mm) increments

Two 3 1/2" x 1 1/2" (89 x 38 mm) knockouts per box

T416BH includes four additional holes in the cover to allow water to enter the inspection well, typically for use with chemical ground rods

### PRODUCT ATTRIBUTES

Material: High Density Polyethylene (HDPE)

Color: Green

Load Rating: 300lb/ft<sup>2</sup>

Diameter, Grade Level (DG): 10 1/4"


Outer Diameter (OD): 13.1"

Height (H): 10"

Unit Weight: 4.5 lb

## DIAGRAMS

---

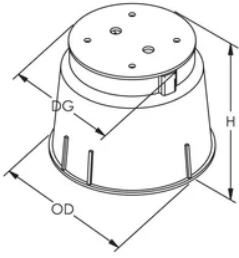

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**