


# Eaton TCF30

Catalog Number: TCF30

Eaton Bussmann series TCF fuse, 30 A, 60 Hz, 50 Hz, Dual, Class CF, Black, With indicator, Blade end, Class CF, Time delay, 100 kAIC at 300 Vdc, 300 kAIC at 600 V, Glass filled PES, 600 V, 300 Vdc

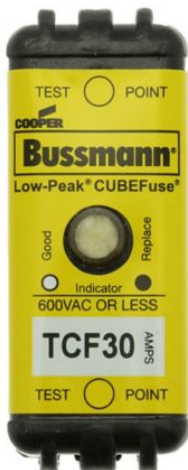

## General specifications

Product Name	Catalog Number
Eaton Bussmann series TCF fuse	TCF30
UPC	Product Length/Depth
051712615037	1.88 in
Product Height	Product Width
1.75 in	0.75 in
Product Weight	Compliances
0.08 lb	RoHS Compliant
Certifications	
UL Listed	
CSA Certified	

## Electrical rating

### Amperage Rating

30 A

### Frequency rating - max

60 Hz

### Frequency rating - min

50 Hz

### Interrupt rating

300 kAIC at 600 Vac

100 kAIC at 300 Vdc

### Voltage rating

600 Vac, 300 Vdc

## Physical details

### Color

Black

### Fuse type

Class CF

Time delay

### Material

Glass filled PES

### Number of elements

Dual

## General information

### Class

Class CF

### Connection

Blade end

### Fuse indicator

With Indicator

### Special features

Finger safe

### Used with

TCFH30N, CCP2-3-30CF

## Resources

### Multimedia

[The Power of Space](#)

[Bussmann series Fuseology](#)

### Specifications and datasheets

[Eaton Specification Sheet - TCF30](#)

### Technical data sheets

[TCF30~CUBEFUSE, TCF 30A IND](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.




[Eaton.com/socialmedia](https://Eaton.com/socialmedia)

# Eaton TCF30

Catalog Number: TCF30

Eaton Bussmann series TCF fuse, 30 A, 60 Hz, 50 Hz, Dual, Class CF, Black, With indicator, Blade end, Class CF, Time delay, 100 kAIC at 300 Vdc, 300 kAIC at 600 V, Glass filled PES, 600 V, 300 Vdc

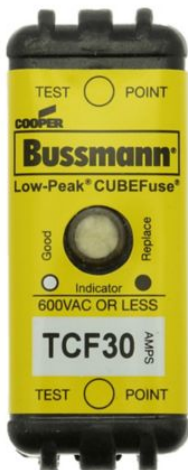

## General specifications

<b>Product Name</b>	<b>Catalog Number</b>
Eaton Bussmann series TCF fuse	TCF30
<b>UPC</b>	<b>Product Length/Depth</b>
051712615037	1.88 in
<b>Product Height</b>	<b>Product Width</b>
1.75 in	0.75 in
<b>Product Weight</b>	<b>Compliances</b>
0.08 lb	RoHS Compliant
<b>Certifications</b>	
UL Listed	
CSA Certified	

## Electrical rating

### Amperage Rating

30 A

### Frequency rating - max

60 Hz

### Frequency rating - min

50 Hz

### Interrupt rating

300 kAIC at 600 Vac

100 kAIC at 300 Vdc

### Voltage rating

600 Vac, 300 Vdc

## Physical details

### Color

Black

### Fuse type

Class CF

Time delay

### Material

Glass filled PES

### Number of elements

Dual

## General information

### Class

Class CF

### Connection

Blade end

### Fuse indicator

With Indicator

### Special features

Finger safe

### Used with

TCFH30N, CCP2-3-30CF

## Resources

### Multimedia

[The Power of Space](#)

[Bussmann series Fuseology](#)

### Specifications and datasheets

[Eaton Specification Sheet - TCF30](#)

### Technical data sheets

[TCF30~CUBEFUSE, TCF 30A IND](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://Eaton.com/socialmedia)