

## TAMPER-RESISTANT THERMOPLASTIC FLOOR BOX COVER, BROWN

TM1542TRBR | [Pass & Seymour](#)

### FEATURES & BENEFITS

Thermoplastic Cover Includes 15 amp 125 volt Decorator receptacle, matching detachable and replacable hinged door; threaded device-mounting holes; drill guides for low-voltage poke-through holes; accepts any Decorator device; mounts on carpeting, hardwood, linoleum, tile floors; Four mounting/leveling screws. Brown.

For detailed Tamper-Resistant receptacle information, visit our [Tamper-Resistant Receptacles](#) page.

- Dual mechanical shutter system to help prevent insertion of foreign objects.
- Auto-ground clip assures positive ground.
- Easily accessed break-off line-contact connecting tab for fast and easy split-circuit wiring.
- Backed-out tri-drive brass terminal screws for faster installation.
- Internal screw-pressure-plate back and side wire capability.
- Two back wire holes for additional wiring flexibility.
- Corrosion-resistant plated steel strap is locked in to face and back body to resist pulling away from the face/body assembly.
- .032 inch thick brass triple-wipe power contacts.
- Two drive screws anchor steel strap to back body and face where abrupt removal torque is greatest.

### SPECIFICATIONS

#### GENERAL INFO

Product Series: Slater  
Component Type: Covers & Flanges

#### LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

CSA Listing Info: No  
CUL Listing No: No  
cULus: No  
cURus: No  
Federal Spec: No  
UL Listing No: No  
UN SPSC: 39121308  
UR: No

## DIMENSIONS

Diameter (US): 6.5"

## TECHNICAL INFORMATION

Material: Plastic


Floor Type: Wood

## BUY AMERICAN ACT COMPLIANCE

Country Of Origin: UNITED STATES OF AMERICA

Buy American Act Status: Buy American Act Compliant



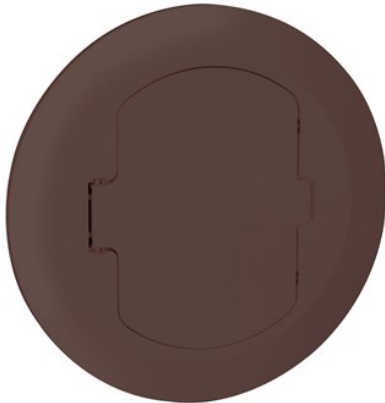

## TAMPER-RESISTANT THERMOPLASTIC FLOOR BOX COVER, BROWN

TM1542TRBR | [Pass & Seymour](#)

### FEATURES & BENEFITS

Thermoplastic Cover Includes 15 amp 125 volt Decorator receptacle, matching detachable and replacable hinged door; threaded device-mounting holes; drill guides for low-voltage poke-through holes; accepts any Decorator device; mounts on carpeting, hardwood, linoleum, tile floors; Four mounting/leveling screws. Brown.

For detailed Tamper-Resistant receptacle information, visit our [Tamper-Resistant Receptacles](#) page.

- Dual mechanical shutter system to help prevent insertion of foreign objects.
- Auto-ground clip assures positive ground.
- Easily accessed break-off line-contact connecting tab for fast and easy split-circuit wiring.
- Backed-out tri-drive brass terminal screws for faster installation.
- Internal screw-pressure-plate back and side wire capability.
- Two back wire holes for additional wiring flexibility.
- Corrosion-resistant plated steel strap is locked in to face and back body to resist pulling away from the face/body assembly.
- .032 inch thick brass triple-wipe power contacts.
- Two drive screws anchor steel strap to back body and face where abrupt removal torque is greatest.

### SPECIFICATIONS

#### GENERAL INFO

Product Series: Slater  
Component Type: Covers & Flanges

#### LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

CSA Listing Info: No  
CUL Listing No: No  
cULus: No  
cURus: No  
Federal Spec: No  
UL Listing No: No  
UN SPSC: 39121308  
UR: No

## DIMENSIONS

Diameter (US): 6.5"

## TECHNICAL INFORMATION

Material: Plastic

Floor Type: Wood

## BUY AMERICAN ACT COMPLIANCE

Country Of Origin: UNITED STATES OF AMERICA

Buy American Act Status: Buy American Act Compliant

