


Straight Blade Receptacles TradeMaster® Decorator Hallway Lights & Combination Devices




Pass & Seymour




Features	
<ul style="list-style-type: none"> Impact-resistant face and body. GE Lexan™ high impact-resistant lens. External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG. Ground screw position under the end of the strap minimizes the risk of contact. Energy-efficient LED has average 20-year life expectancy: eliminates bulb replacement. Sensor automatically turns light ON in the dark. 	<ul style="list-style-type: none"> Increased light output for better illumination. Light sensor for enhanced sensitivity. <p>Tamper-Resistant Combination Version:</p> <ul style="list-style-type: none"> UL tested shutter mechanism for protection against improper object insertion per UL478. Specially designed for increased protection of children in their homes. Superior protection than traditional outlet “caps” or “protection plates.”

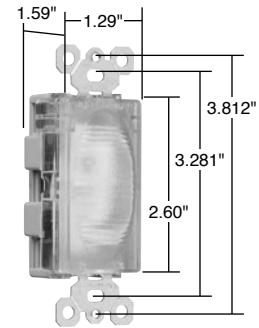


TMHWLCC

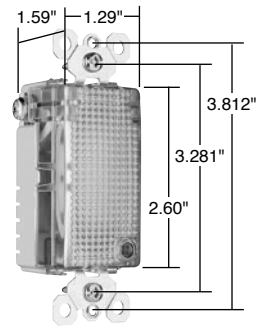

TMHWLECC

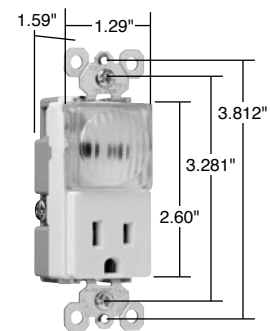

TM8HWLWCC

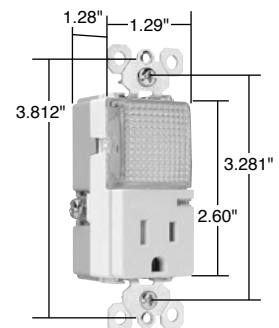

TM8HWLTRLACC

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	3rd Party Compliance	
				UL US	UL1598
TradeMaster® Decorator Full Hallway Light with Light Sensor					
TMHWLCC	— 120	0.1328	Clear		•
Enhanced Decorator Full Hallway Light with Light Sensor					
TMHWLECC	— 120	1.079	Clear		•
Enhanced Decorator Full Hallway Light without Light Sensor					
TMHWLENSCC	— 120	1.113	Clear		•
Full Hallway Decorator Light for use with P&S Metal Louver Plates**					
TMHWLLOUVCC	— 120	0.0843	Clear		•

*FCD = Foot Candle Distance, 1 Lumen = 1 FCD. See page S-56 for more information.

**For Louver Plates, see Page Q-21.

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	NEMA Config. No.	3rd Party Compliance	
					UL US	UL498
TradeMaster® Decorator Hallway Light & Single Receptacle						
TM8HWLICC	15 120/125	0.1442	Ivory	5-15R		•
TM8HWLWCC	15 120/125	0.1442	White	5-15R		•
TM8HWLCC	15 120/125	0.1442	Brown	5-15R		•
TM8HWLBKCC	15 120/125	0.1442	Black	5-15R		•
TM8HWLLACC	15 120/125	0.1442	Light Almond	5-15R		•
Decorator Hallway Light with High Output Light & Tamper-Resistant Single Receptacle						
TM8HWLTRICC	15 125	0.2561	Ivory	5-15R		•
TM8HWLTRWCC	15 125	0.2561	White	5-15R		•
TM8HWLTRCC	15 125	0.2561	Brown	5-15R		•
TM8HWLTRBKCC	15 125	0.2561	Black	5-15R		•
TM8HWLTRLACC	15 125	0.2561	Light Almond	5-15R		•

*FCD = Foot Candle Distance. 1 Lumen = 1 FCD. See page S-56 for more information.

For complete line of Decorator Combination Devices, see Pages D-9 – D-12, D-20, D-24, D-33 and D-39.

All devices listed on this page conform to NEMA WD-1 and WD-6.

Straight Blade Receptacles

Hallway Lights & Combination Devices

Devices & Wall Plates Color Selection Chart



Pass & Seymour

Devices & Plastic Wall Plate Colors

Ivory	Light Almond	White	Green		
Black	Blue	Brown	Gray	Orange	Red

See specific device and wall plate catalog charts for particular color availabilities.

Metal Wall Plates

Aluminum	Brass (Brushed)	Polished Brass	Stainless Steel	Brushed Bronze	Chrome

Metal Finish

Custom Metal Wall Plates Paint Finish Colors

Orange	Green	Gray	Yellow	Glossy Black	Brown	White
Primer	Red	Pink	Flat Black	Ivory	Light Almond	Blue

Paint Color

To order custom metal wall plates, see Pages Q-43 – Q-45.

For additional colors consult factory.


Straight Blade Receptacles TradeMaster® Decorator Hallway Lights & Combination Devices




Pass & Seymour




Features	
<ul style="list-style-type: none"> ■ Impact-resistant face and body. ■ GE Lexan™ high impact-resistant lens. ■ External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG. ■ Ground screw position under the end of the strap minimizes the risk of contact. ■ Energy-efficient LED has average 20-year life expectancy: eliminates bulb replacement. ■ Sensor automatically turns light ON in the dark. 	<ul style="list-style-type: none"> ■ Increased light output for better illumination. ■ Light sensor for enhanced sensitivity. <p>Tamper-Resistant Combination Version:</p> <ul style="list-style-type: none"> ■ UL tested shutter mechanism for protection against improper object insertion per UL478. ■ Specially designed for increased protection of children in their homes. ■ Superior protection than traditional outlet “caps” or “protection plates.”

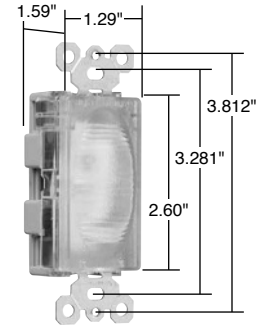


TMHWLCC

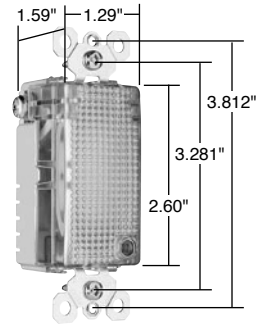

TMHWLECC

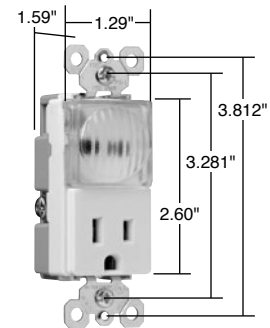

TM8HWLWCC

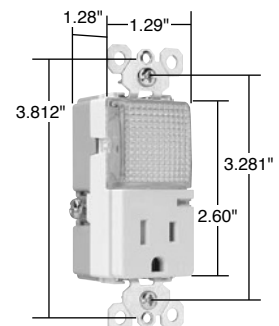

TM8HWLTRLACC

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	3rd Party Compliance	
					UL1598
TradeMaster® Decorator Full Hallway Light with Light Sensor					
TMHWLCC	— 120	0.1328	Clear		•
Enhanced Decorator Full Hallway Light with Light Sensor					
TMHWLECC	— 120	1.079	Clear		•
Enhanced Decorator Full Hallway Light without Light Sensor					
TMHWLENSCC	— 120	1.113	Clear		•
Full Hallway Decorator Light for use with P&S Metal Louver Plates**					
TMHWLLOUVCC	— 120	0.0843	Clear		•

*FCD = Foot Candle Distance, 1 Lumen = 1 FCD. See page S-56 for more information.

**For Louver Plates, see Page Q-21.

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	NEMA Config. No.	3rd Party Compliance	
						UL498
TradeMaster® Decorator Hallway Light & Single Receptacle						
TM8HWLICC	15 120/125	0.1442	Ivory	5-15R		•
TM8HWLWCC	15 120/125	0.1442	White	5-15R		•
TM8HWLCC	15 120/125	0.1442	Brown	5-15R		•
TM8HWLBKCC	15 120/125	0.1442	Black	5-15R		•
TM8HWLLACC	15 120/125	0.1442	Light Almond	5-15R		•
Decorator Hallway Light with High Output Light & Tamper-Resistant Single Receptacle						
TM8HWLTRICC	15 125	0.2561	Ivory	5-15R		•
TM8HWLTRWCC	15 125	0.2561	White	5-15R		•
TM8HWLTRCC	15 125	0.2561	Brown	5-15R		•
TM8HWLTRBKCC	15 125	0.2561	Black	5-15R		•
TM8HWLTRLACC	15 125	0.2561	Light Almond	5-15R		•

*FCD = Foot Candle Distance. 1 Lumen = 1 FCD. See page S-56 for more information.

For complete line of Decorator Combination Devices, see Pages D-9 – D-12, D-20, D-24, D-33 and D-39.

All devices listed on this page conform to NEMA WD-1 and WD-6.

Straight Blade Receptacles

Hallway Lights & Combination Devices

Devices & Wall Plates Color Selection Chart



Pass & Seymour

Devices & Plastic Wall Plate Colors

Ivory	Light Almond	White	Green		
Black	Blue	Brown	Gray	Orange	Red

See specific device and wall plate catalog charts for particular color availabilities.

Metal Wall Plates

Metal Finish Aluminum	Brass (Brushed)	Polished Brass	Stainless Steel	Brushed Bronze	Chrome

Custom Metal Wall Plates Paint Finish Colors

Paint Color Orange	Green	Gray	Yellow	Glossy Black	Brown	White
Paint Color Primer	Red	Pink	Flat Black	Ivory	Light Almond	Blue

To order custom metal wall plates, see Pages Q-43 – Q-45.

For additional colors consult factory.