


# Specifications

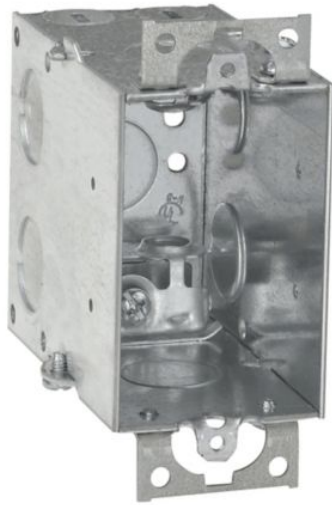

## Eaton TP244

Eaton Crouse-Hinds series Switch Box, (1) 1/2", 2, AC/MC clamps, 3-1/2", (1) 1/2", Steel, (2) 1/2", Ears, Gangable, 18.0 cubic inch capacity

### General specifications

<b>PRODUCT NAME</b>	Eaton Crouse-Hinds series switch box
<b>CATALOG NUMBER</b>	TP244
<b>UPC</b>	786189102444
<b>PRODUCT LENGTH/DEPTH</b>	2 in
<b>PRODUCT HEIGHT</b>	3 in
<b>PRODUCT WIDTH</b>	3.5 in
<b>PRODUCT WEIGHT</b>	0.81 lb



*Powering Business Worldwide*

### Certifications and compliances

<b>AREA CLASSIFICATION</b>	Ordinary/Non-Hazardous Locations
<b>STANDARDS TYPE</b>	NEC/CEC

### Product specifications

<b>DEPTH</b>	3-1/2"
<b>TYPE</b>	Gangable
<b>CAPACITY</b>	18 cubic in
<b>CONDUIT/CABLE</b>	AC/MC clamps

<b>END KNOCKOUTS</b>	(1) 1/2 in
<b>SIDE KNOCKOUTS</b>	(2) 1/2 in
<b>BOTTOM KNOCKOUTS</b>	(1) 1/2 in
<b>CABLE KNOCKOUTS</b>	2
<b>MATERIAL</b>	Steel
<b>SPECIAL FEATURES</b>	Ears

## Resources

**CATALOGS** [Crouse-Hinds series Steel Switch Boxes catalog page](#)

**CERTIFICATION REPORTS** [Steel Switch Boxes Canadian certification](#)

[Steel Switch Boxes UL certification](#)

**SPECIFICATIONS AND DATASHEETS**

[Steel Outlet Boxes for Electrical Systems](#)

[Eaton Specification Sheet - TP244](#)

**PROJECT NAME:**

**PROJECT NUMBER:**

**PREPARED BY:**

**DATE:**



**Eaton Corporation plc**  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com

© 2025 Eaton. All Rights Reserved.


Eaton is a registered trademark.

All other trademarks are property of their respective owners.

Follow us on social media to get the latest product and support information.



# Specifications

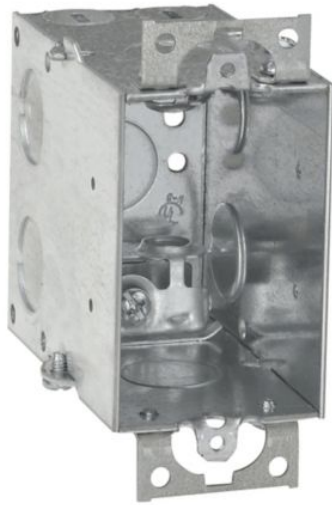

## Eaton TP244

Eaton Crouse-Hinds series Switch Box, (1) 1/2", 2, AC/MC clamps, 3-1/2", (1) 1/2", Steel, (2) 1/2", Ears, Gangable, 18.0 cubic inch capacity

### General specifications

<b>PRODUCT NAME</b>	Eaton Crouse-Hinds series switch box
<b>CATALOG NUMBER</b>	TP244
<b>UPC</b>	786189102444
<b>PRODUCT LENGTH/DEPTH</b>	2 in
<b>PRODUCT HEIGHT</b>	3 in
<b>PRODUCT WIDTH</b>	3.5 in
<b>PRODUCT WEIGHT</b>	0.81 lb



### Certifications and compliances

<b>AREA CLASSIFICATION</b>	Ordinary/Non-Hazardous Locations
<b>STANDARDS TYPE</b>	NEC/CEC

### Product specifications

<b>DEPTH</b>	3-1/2"
<b>TYPE</b>	Gangable
<b>CAPACITY</b>	18 cubic in
<b>CONDUIT/CABLE</b>	AC/MC clamps

<b>END KNOCKOUTS</b>	(1) 1/2 in
<b>SIDE KNOCKOUTS</b>	(2) 1/2 in
<b>BOTTOM KNOCKOUTS</b>	(1) 1/2 in
<b>CABLE KNOCKOUTS</b>	2
<b>MATERIAL</b>	Steel
<b>SPECIAL FEATURES</b>	Ears

## Resources

### CATALOGS

[Crouse-Hinds series Steel Switch Boxes catalog page](#)

### CERTIFICATION REPORTS

[Steel Switch Boxes Canadian certification](#)

[Steel Switch Boxes UL certification](#)

### SPECIFICATIONS AND DATASHEETS

[Steel Outlet Boxes for Electrical Systems](#)

[Eaton Specification Sheet - TP244](#)

**PROJECT NAME:**

**PROJECT NUMBER:**

**PREPARED BY:**

**DATE:**



**Eaton Corporation plc**  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com

© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.

Follow us on social media to get the latest product and support information.

