
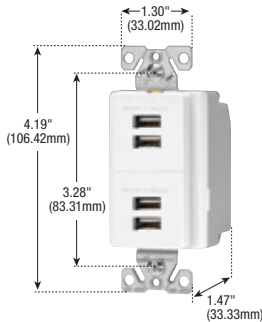


# Commercial grade receptacles


## Commercial grade straight blade receptacles

### Product description


2-pole, 3-wire grounding  
15A, 125V/AC  
20A, 125V/AC  
NEMA 5-15R, 5-20R

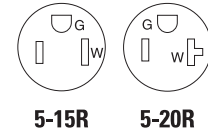


7750

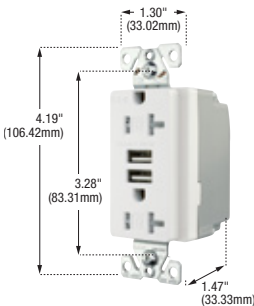

TR7756

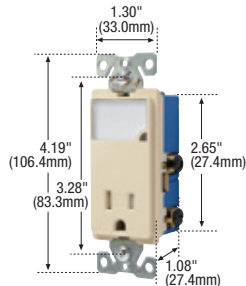

TR7735

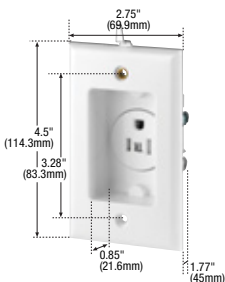

TR775

### USB charging station



USB rating		Description	Color suffix	Catalog no.
A	V/DC			
5.0 total	5	USB charging station, wire leads	BK, LA, V, W	□ 7750__

### USB charger with tamper resistant receptacles



Rating				Description	Color suffix	Catalog no.
A	V/AC	Amps	V/DC			
15	125	3.1	5	USB charger with TR duplex receptacle, wire leads	A, B, BK, GY, LA, V, W	□ TR7755__
20	125	3.1	5	USB charger with TR duplex receptacle, wire leads	A, B, BK, GY, LA, V, W	□ TR7756__

### Tamper resistant combination LED wallbox nightlight with receptacle



Rating				Description	Color suffix	Catalog no.
A	V/AC	NEMA				
15	125	5-15R		Nightlight with single receptacle, back & side wire	A, BK, LA, V, W	□ TR7735
20	125	5-20R		Nightlight with single receptacle, back & side wire	A, BK, LA, V, W	□ TR7736

### Tamper resistant clock hanger receptacles



Rating				Description	Color	Catalog No.	
A	V/AC	NEMA					
15	125	5-15R		Single clock hanger receptacle side wire	W	□ TR775W	●
				Recessed duplex receptacle, push wire & side wire	W	□ TR780W	●

### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), V (Ivory), W (White)

A	B	BK	GY	LA	V	W
(Almond)	(Brown)	(Black)	(Gray)	(Lt. Almond)	(Ivory)	(White)

**Specification information:** USB commercial receptacles & USB charging station: A-34

**Compliances, specifications and availability are subject to change without notice.**

Tamper resistant



RoHS compliant - Page Q-32

# Commercial grade receptacles


## Commercial grade straight blade receptacles

### Product description


2-pole, 3-wire grounding  
15A, 125V/AC  
20A, 125V/AC  
NEMA 5-15R, 5-20R

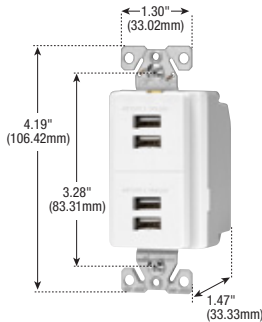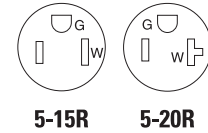


7750

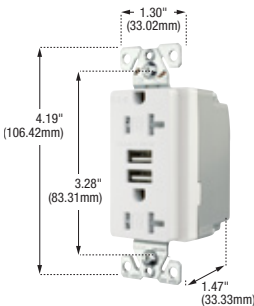

TR7756

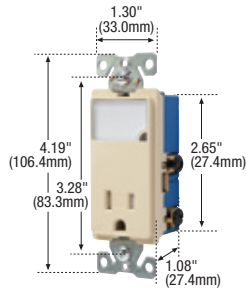

TR7735

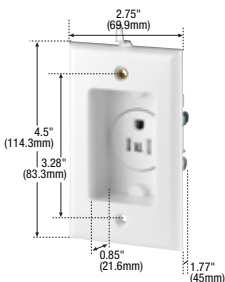

TR775

### USB charging station



USB rating		Description	Color suffix	Catalog no.
A	V/DC			
5.0 total	5	USB charging station, wire leads	BK, LA, V, W	□ 7750__

### USB charger with tamper resistant receptacles



Rating				Description	Color suffix	Catalog no.
A	V/AC	Amps	V/DC			
15	125	3.1	5	USB charger with TR duplex receptacle, wire leads	A, B, BK, GY, LA, V, W	□ TR7755__
20	125	3.1	5	USB charger with TR duplex receptacle, wire leads	A, B, BK, GY, LA, V, W	□ TR7756__

### Tamper resistant combination LED wallbox nightlight with receptacle



Rating				Description	Color suffix	Catalog no.
A	V/AC	NEMA				
15	125	5-15R		Nightlight with single receptacle, back & side wire	A, BK, LA, V, W	□ TR7735
20	125	5-20R		Nightlight with single receptacle, back & side wire	A, BK, LA, V, W	□ TR7736

 
### Tamper resistant clock hanger receptacles



Rating				Description	Color	Catalog No.	
A	V/AC	NEMA					
15	125	5-15R		Single clock hanger receptacle side wire	W	□ TR775W	•
				Recessed duplex receptacle, push wire & side wire	W	□ TR780W	•

### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), V (Ivory), W (White)



**Specification information:** USB commercial receptacles & USB charging station: A-34  
**Compliances, specifications and availability are subject to change without notice.**

