
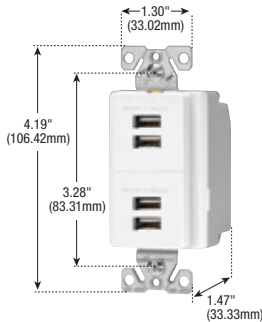


Commercial grade receptacles


Commercial grade straight blade receptacles

Product description


2-pole, 3-wire grounding
15A, 125V/AC
20A, 125V/AC
NEMA 5-15R, 5-20R

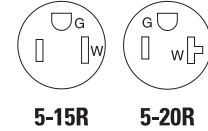


7750

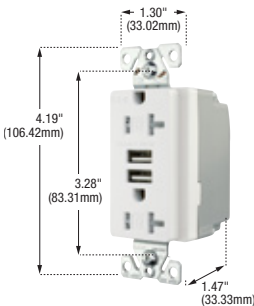

TR7756

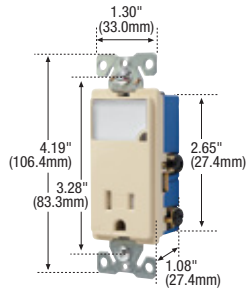

TR7735

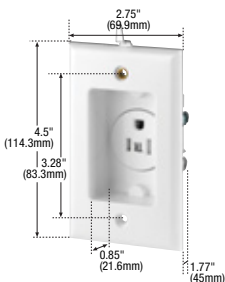

TR775

USB charging station



USB rating		Description	Color suffix	Catalog no.
A	V/DC			
5.0 total	5	USB charging station, wire leads	BK, LA, V, W	□ 7750__

USB charger with tamper resistant receptacles



Rating				Description	Color suffix	Catalog no.
A	V/AC	Amps	V/DC			
15	125	3.1	5	USB charger with TR duplex receptacle, wire leads	A, B, BK, GY, LA, V, W	□ TR7755__
20	125	3.1	5	USB charger with TR duplex receptacle, wire leads	A, B, BK, GY, LA, V, W	□ TR7756__

Tamper resistant combination LED wallbox nightlight with receptacle



Rating				Description	Color suffix	Catalog no.
A	V/AC	NEMA				
15	125	5-15R		Nightlight with single receptacle, back & side wire	A, BK, LA, V, W	□ TR7735
20	125	5-20R		Nightlight with single receptacle, back & side wire	A, BK, LA, V, W	□ TR7736

Tamper resistant clock hanger receptacles



Rating				Description	Color	Catalog No.	
A	V/AC	NEMA					
15	125	5-15R		Single clock hanger receptacle side wire	W	□ TR775W	●
				Recessed duplex receptacle, push wire & side wire	W	□ TR780W	●

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), V (Ivory), W (White)

A	B	BK	GY	LA	V	W
(Almond)	(Brown)	(Black)	(Gray)	(Lt. Almond)	(Ivory)	(White)

Specification information: USB commercial receptacles & USB charging station: A-34

Compliances, specifications and availability are subject to change without notice.

Tamper resistant



RoHS compliant - Page Q-32

Commercial grade receptacles


Commercial grade straight blade receptacles

Product description


2-pole, 3-wire grounding
15A, 125V/AC
20A, 125V/AC
NEMA 5-15R, 5-20R

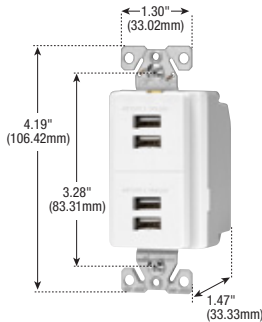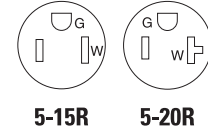


7750

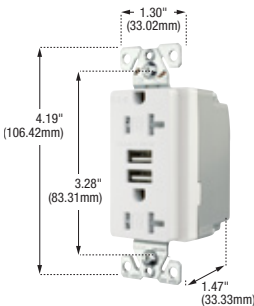

TR7756

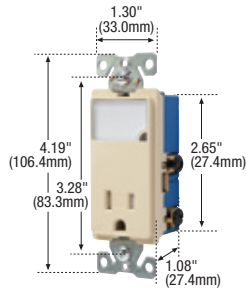

TR7735

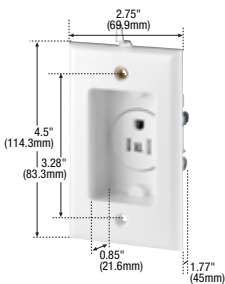

TR775

USB charging station



USB rating		Description	Color suffix	Catalog no.
A	V/DC			
5.0 total	5	USB charging station, wire leads	BK, LA, V, W	□ 7750__

USB charger with tamper resistant receptacles



Rating				Description	Color suffix	Catalog no.
A	V/AC	Amps	V/DC			
15	125	3.1	5	USB charger with TR duplex receptacle, wire leads	A, B, BK, GY, LA, V, W	□ TR7755__
20	125	3.1	5	USB charger with TR duplex receptacle, wire leads	A, B, BK, GY, LA, V, W	□ TR7756__

Tamper resistant combination LED wallbox nightlight with receptacle



Rating			Description	Color suffix	Catalog no.
A	V/AC	NEMA			
15	125	5-15R	Nightlight with single receptacle, back & side wire	A, BK, LA, V, W	□ TR7735
20	125	5-20R	Nightlight with single receptacle, back & side wire	A, BK, LA, V, W	□ TR7736

Tamper resistant clock hanger receptacles



Rating			Description	Color	Catalog No.	
A	V/AC	NEMA				
15	125	5-15R	Single clock hanger receptacle side wire	W	□ TR775W	•
			Recessed duplex receptacle, push wire & side wire	W	□ TR780W	•

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), V (Ivory), W (White)

A	B	BK	GY	LA	V	W
(Almond)	(Brown)	(Black)	(Gray)	(Lt. Almond)	(Ivory)	(White)

Specification information: USB commercial receptacles & USB charging station: A-34

Compliances, specifications and availability are subject to change without notice.

Tamper resistant

RoHS compliant - Page Q-32