




SWB-1, 2, 3







SWB-4, 5, 6

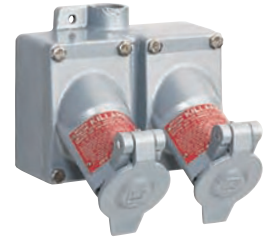

Single Gang



Double Gang

| RECEPTACLES AND ASSEMBLIES ^④ | | | | | |
|--|-----------------|----------|---|---|---|
| NEMA RATING & CONFIGURATION | ENCLOSURE STYLE | HUB SIZE | SINGLE GANG ^{③④} GROUPS C, D, F, & G | DOUBLE GANG ^{③④} GROUPS C, D, F, & G | SINGLE GANG ^{①②} GROUPS B, C, D, F & G |
|  <p>20 Amp 125 Volt 2 POLE 3 WIRE 5-20R</p> | RECEPTACLE ONLY | — | UGR0-20231 | UGR0-20231 | — |
| | DEAD END | 1/2" | UGR1-20231 | UGR7-20231 | UGRB1-20231 |
| | | 3/4" | UGR2-20231 | UGR8-20231 | UGRB2-20231 |
| | | 1" | UGR3-20231 | UGR9-20231 | UGRB3-20231 |
| | FEED-THRU | 1/2" | UGR4-20231 | UGR10-20231 | UGRB4-20231 |
| | | 3/4" | UGR5-20231 | UGR11-20231 | UGRB5-20231 |
| | | 1" | UGR6-20231 | UGR12-20231 | UGRB6-20231 |
|  <p>15 Amp 125 Volt 2 POLE 3 WIRE 5-15R</p> | RECEPTACLE ONLY | — | UGR0C-15231 | UGR0C-15231 | — |
| | DEAD END | 1/2" | UGR1C-15231 | UGR7C-15231 | UGRB1C-15231 |
| | | 3/4" | UGR2C-15231 | UGR8C-15231 | UGRB2C-15231 |
| | | 1" | UGR3C-15231 | UGR9C-15231 | UGRB3C-15231 |
| | FEED-THRU | 1/2" | UGR4C-15231 | UGR10C-15231 | UGRB4C-15231 |
| | | 3/4" | UGR5C-15231 | UGR11C-15231 | UGRB5C-15231 |
| | | 1" | UGR6C-15231 | UGR12C-15231 | UGRB6C-15231 |
|  <p>20 Amp 250 Volt 2 POLE 3 WIRE 6-20R</p> | RECEPTACLE ONLY | — | UGR0-20232 | UGR0-20232 | — |
| | DEAD END | 1/2" | UGR1-20232 | UGR7-20232 | UGRB1-20232 |
| | | 3/4" | UGR2-20232 | UGR8-20232 | UGRB2-20232 |
| | | 1" | UGR3-20232 | UGR9-20232 | UGRB3-20232 |
| | FEED-THRU | 1/2" | UGR4-20232 | UGR10-20232 | UGRB4-20232 |
| | | 3/4" | UGR5-20232 | UGR11-20232 | UGRB5-20232 |
| | | 1" | UGR6-20232 | UGR12-20232 | UGRB6-20232 |
|  <p>15 Amp 250 Volt 2 POLE 3 WIRE 6-15R</p> | RECEPTACLE ONLY | — | UGR0C-15232 | UGR0C-15232 | — |
| | DEAD END | 1/2" | UGR1C-15232 | UGR7C-15232 | UGRB1C-15232 |
| | | 3/4" | UGR2C-15232 | UGR8C-15232 | UGRB2C-15232 |
| | | 1" | UGR3C-15232 | UGR9C-15232 | UGRB3C-15232 |
| | FEED-THRU | 1/2" | UGR4C-15232 | UGR10C-15232 | UGRB4C-15232 |
| | | 3/4" | UGR5C-15232 | UGR11C-15232 | UGRB5C-15232 |
| | | 1" | UGR6C-15232 | UGR12C-15232 | UGRB6C-15232 |

① Items in this column are suitable for Class I, Group B in addition to Class I, Groups C, D.

Also suitable for Class I, Zone 1, Groups IIB+H2, IIA.

② Seals must be installed within 6 inches of conduit opening.

③ Items in this column may also be used in Class I, Zone 1, Groups IIB, IIA.

Assembly numbers not rated for Group B are shipped as receptacle & back box components.

④ Refer to page C19 for additional SWB Series Back Box configurations.

⑤ Canada only configuration

⑥ Canadian Codes now allow "T" combination slots for 15A or 20A plugs. Check breaker and wire feed size for proper application ratings.

NOTE: For replacement receptacle cover and hinge, order KIT-173.






SWB-1, 2, 3



SWB-4, 5, 6



Single Gang

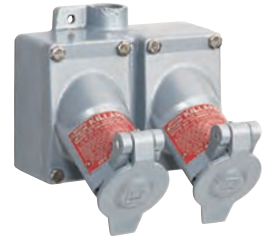

Double Gang

| RECEPTACLES AND ASSEMBLIES ^④ | | | | | |
|---|-----------------|----------|---|---|---|
| NEMA RATING & CONFIGURATION | ENCLOSURE STYLE | HUB SIZE | SINGLE GANG ^{③④} GROUPS C, D, F, & G | DOUBLE GANG ^{③④} GROUPS C, D, F, & G | SINGLE GANG ^{①②} GROUPS B, C, D, F & G |
| 20 Amp 125 Volt 2 POLE 3 WIRE 5-20R | RECEPTACLE ONLY | — | UGR0-20231 | UGR0-20231 | — |
| | DEAD END | 1/2" | UGR1-20231 | UGR7-20231 | UGRB1-20231 |
| | | 3/4" | UGR2-20231 | UGR8-20231 | UGRB2-20231 |
| | | 1" | UGR3-20231 | UGR9-20231 | UGRB3-20231 |
| | FEED-THRU | 1/2" | UGR4-20231 | UGR10-20231 | UGRB4-20231 |
| | | 3/4" | UGR5-20231 | UGR11-20231 | UGRB5-20231 |
| | | 1" | UGR6-20231 | UGR12-20231 | UGRB6-20231 |
| 15 Amp 125 Volt 2 POLE 3 WIRE 5-15R | RECEPTACLE ONLY | — | UGR0C-15231 | UGR0C-15231 | — |
| | DEAD END | 1/2" | UGR1C-15231 | UGR7C-15231 | UGRB1C-15231 |
| | | 3/4" | UGR2C-15231 | UGR8C-15231 | UGRB2C-15231 |
| | | 1" | UGR3C-15231 | UGR9C-15231 | UGRB3C-15231 |
| | FEED-THRU | 1/2" | UGR4C-15231 | UGR10C-15231 | UGRB4C-15231 |
| | | 3/4" | UGR5C-15231 | UGR11C-15231 | UGRB5C-15231 |
| | | 1" | UGR6C-15231 | UGR12C-15231 | UGRB6C-15231 |
| 20 Amp 250 Volt 2 POLE 3 WIRE 6-20R | RECEPTACLE ONLY | — | UGR0-20232 | UGR0-20232 | — |
| | DEAD END | 1/2" | UGR1-20232 | UGR7-20232 | UGRB1-20232 |
| | | 3/4" | UGR2-20232 | UGR8-20232 | UGRB2-20232 |
| | | 1" | UGR3-20232 | UGR9-20232 | UGRB3-20232 |
| | FEED-THRU | 1/2" | UGR4-20232 | UGR10-20232 | UGRB4-20232 |
| | | 3/4" | UGR5-20232 | UGR11-20232 | UGRB5-20232 |
| | | 1" | UGR6-20232 | UGR12-20232 | UGRB6-20232 |
| 15 Amp 250 Volt 2 POLE 3 WIRE 6-15R | RECEPTACLE ONLY | — | UGR0C-15232 | UGR0C-15232 | — |
| | DEAD END | 1/2" | UGR1C-15232 | UGR7C-15232 | UGRB1C-15232 |
| | | 3/4" | UGR2C-15232 | UGR8C-15232 | UGRB2C-15232 |
| | | 1" | UGR3C-15232 | UGR9C-15232 | UGRB3C-15232 |
| | FEED-THRU | 1/2" | UGR4C-15232 | UGR10C-15232 | UGRB4C-15232 |
| | | 3/4" | UGR5C-15232 | UGR11C-15232 | UGRB5C-15232 |
| | | 1" | UGR6C-15232 | UGR12C-15232 | UGRB6C-15232 |

① Items in this column are suitable for Class I, Group B in addition to Class I, Groups C, D.

Also suitable for Class I, Zone 1, Groups IIB+H2, IIA.

② Seals must be installed within 6 inches of conduit opening.

③ Items in this column may also be used in Class I, Zone 1, Groups IIB, IIA.

Assembly numbers not rated for Group B are shipped as receptacle & back box components.

④ Refer to page C19 for additional SWB Series Back Box configurations.

⑤ Canada only configuration

⑥ Canadian Codes now allow "T" combination slots for 15A or 20A plugs. Check breaker and wire feed size for proper application ratings.

NOTE: For replacement receptacle cover and hinge, order KIT-173.