



Vaportight Lighting & Accessories
T&B Catalog Number:

UPC Number:
Status:
Description:

VGL-02
 04226952510
 Active

200-Watt Glass Globe

Features

Fully threaded globes prevent cross threading assuring a tight seal.

Application

Low maintenance indoor/outdoor lighting where moisture, dirt, dust, corrosion and rough service are problems.

To light cold storage facilities, walkways, bridges, tunnels and security locations.

Used with colored globes as warning, caution or directional lights.

General

Globe Material	Lime Crystal Glass
Maximum Wattage	200

Dimension Information

Inner Diameter (inches)	31 3/16
A (inches)	4 3/8
B (inches)	8 3/8
C (inches)	4 5/16
D (inches)	1

Packaging

T&B Order Multiple	6
T&B Inner Pack	1
Package in Units	6
T&B Sold in UOM	Each
T&B Weight Per UOM	2 lbs. Each

Application Support

Product Overview	Available on Website
D-Pak Merchandising System	Available on Website
Industry Cross Reference	Available on Website


Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
 E 51152

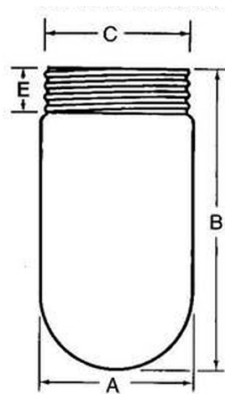

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com




Vaportight Lighting & Accessories
T&B Catalog Number:

UPC Number:
Status:
Description:

VGL-02
 04226952510
 Active

200-Watt Glass Globe

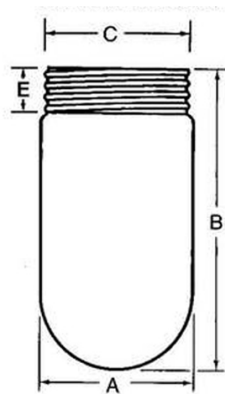

Features

Fully threaded globes prevent cross threading assuring a tight seal.

Application

Low maintenance indoor/outdoor lighting where moisture, dirt, dust, corrosion and rough service are problems.

To light cold storage facilities, walkways, bridges, tunnels and security locations.

Used with colored globes as warning, caution or directional lights.

General

Globe Material	Lime Crystal Glass
Maximum Wattage	200

Dimension Information

Inner Diameter (inches)	31 3/16
A (inches)	4 3/8
B (inches)	8 3/8
C (inches)	4 5/16
D (inches)	1

Packaging

T&B Order Multiple	6
T&B Inner Pack	1
Package in Units	6
T&B Sold in UOM	Each
T&B Weight Per UOM	2 lbs. Each

Application Support

Product Overview	Available on Website
D-Pak Merchandising System	Available on Website
Industry Cross Reference	Available on Website

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
 E 51152

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com