


COOPER LIGHTING - LUMARK

DIMENSIONS

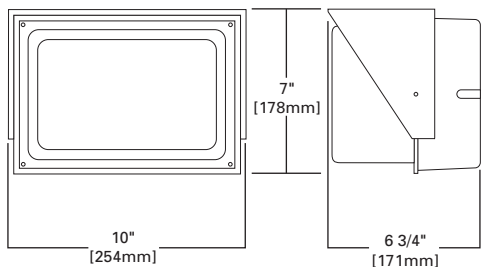

DESCRIPTION

The Lumark Glass-Pak is constructed of premium die-cast aluminum and features a borosilicate glass lens.




GP GLASS-PAK

35-175W
High Pressure Sodium
Pulse Start Metal Halide
Metal Halide

WALL MOUNT
LUMINAIRE

MOUNTING DETAIL

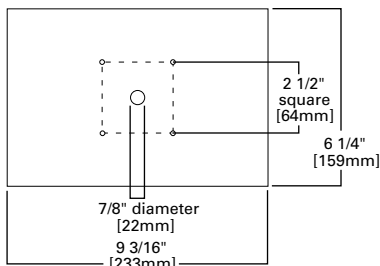

ORDERING INFORMATION

SAMPLE NUMBER: MPPG-150H-MT-LL

Lamp Type MP =Pulse Start Metal Halide MH =Metal Halide ¹ HP =High Pressure Sodium Series GP =Glass-Pak	Lamp Wattage ¹ MP 50=50W 70=70W 100=100W 150=150W MH 175=175W ¹ HP 35=35W ³ 50=50W ³ 70=70W 100=100W 150=150W	Ballast ⁴ H =High Power Factor = =Normal Power Factor	Voltage ⁵ 120V 208V 240V 277V 347V 480V ³ DT =Dual-Tap MT =Multi-Tap wired 277V TT =Triple-Tap wired 347V	Options ⁶ LL =Lamp Included ⁷ TR =Tamper Resistant Screws F1 =Single Fuse (120, 277 or 347V only) F2 =Double Fused (208, 240 or 480V only) PE =Internal Photocontrol (Specify Voltage) PC =Button Type Photocontrol	Accessories ⁸ UB-U Universal BKT =Universal Mounting Bracket WG/GP-GS =Wire Guard PE-480V =Field Installed Photocontrol, 480V PE-347V =Field Installed Photocontrol, 347V PE/MT =Field Installed Photocontrol TRSD-8/32 =Tamper-Resistant Screwdriver
---	--	---	--	--	---

NOTES: 1 All HID lamps are medium-base. 175W MH is available for non-US markets only. 2 35W is HP only, 120V only. 3 480V not available in 35 or 50W. 4 High Power Factor ballast required on all MP and MH products. 5 Products also available in non-US voltages and 50Hz for international markets. Consult factory for availability and ordering. 6 Add as suffix in the order shown. 7 Lamp is shipped separate from luminaire. Lamp is Cooper designated product based on luminaire requirements. Specified lamps must be ordered as a separate line item. 8 Order separately. 9 Specifications and dimensions subject to change without notice.

STOCK SAMPLE NUMBER (LAMP INCLUDED)

SAMPLE NUMBER: MPPG-70H-DT-LL

Lamp Type MP =Pulse Start Metal Halide	Series GP =Glass Pak	Lamp Wattage 70H=70W 100H=100W 150H=150W	Voltage DT =Dual-Tap ¹ MT =Multi-Tap	Options LL =Lamp Included
---	---------------------------------------	--	--	--

NOTES: 1 Dual-Tap available on 70W. Standard multi-tap and bronze. Refer to In-Stock Guide for availability. Options not available with stock products. Order accessories as separate item for field installation. Refer to standard ordering information to add options and accessories.

- U.L. listed for wet locations. CSA certified
- Die-cast aluminum housing finished in architectural dark bronze polyester powder coat
- Precision aluminum reflector/visor system directs light down and out, eliminating glare and wasted light
- Optical system is sealed with foam-in-place silicone gasketing
- Can be mounted to any vertical surface. 1/2" knockouts on side of housing accommodate surface-mounted conduit, or back plate can be mounted to 4" octagonal J-box
- Prismatic borosilicate glass refractor provides excellent beam distribution without lens yellowing
- Approximate net weight: 18 lbs. (8 kgs.)

Lamp Type	Wattage
Pulse Start Metal Halide (MP)	70, 100, 150W
Metal Halide (MH)	175W
High Pressure Sodium (HP)	70, 100, 150W

Voltage Chart	
DT=Dual-Tap	120/277V (wired 277V)
MT=Multi-Tap	120/208/240/277V (wired 277V)
TT=Triple-Tap	120/277/347V (wired 347V)