

COMPRESSION CONNECTORS
Dual Rated Wide Range
Tap Connectors
and Covers
WRD, C SERIES



DUAL RATED WIDE RANGE TAP CONNECTORS

- For combinations of aluminum and aluminum-copper conductors.
- Standard compression tools and dies install all sizes.
- Formable ribs provide broader contact area.
- Fold-in tabs provide positive tab interlock as tool closes.
- Made from high strength aluminum alloy.
- All connectors are reversible.

RATINGS

RATING:
 600V.

FOR TOOL & DIE CRIMPING INFORMATION,
 PLEASE SEE TABLE ON PAGE 149

DUAL RATED INSULATING COVERS


- Hinged polyurethane cover for easy installation of WRD series tap connectors.
- Eliminates taping.
- Drain ports prevent accumulation of moisture.
- Ultraviolet stabilized.



CAT. NO.	CAPACITY	STD. CTN. QTY.
C2	All 5/8" OD. Sleeve 2" long or less	12
C5	All "O" die taps 1 3/4" long or less	12
C7	All "D" die taps 2 1/2" long or less	6
C9	All "N" die taps up to 2" long	4



Scan QR to view
 Tool & Die Charts

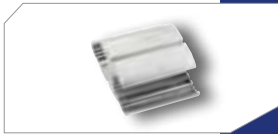

CAT. NO.	STANDARD CONDUCTOR RANGE						COMPACT CONDUCTOR				STD. CTN. QTY.
	A GROOVE			B GROOVE			A GROOVE		B GROOVE		
	ACSR	STR	SOL	ACSR	STR	SOL	ACSR	STR	ACSR	STR	
WRD159	-	1	-	-	1	-	1	1	1	1	25
	2	2	2	2	2	2	2	2	2	2	25
	3	3	3	3	3	3	3	3	3	3	25
	4	4	4	4	4	4	4	4	4	4	25
	6	6	6	6	6	6	6	6	6	6	25
WRD189	-	-	3/0	-	-	1/0	-	-	-	-	25
	-	2/0	2/0	-	1	1	2/0	2/0	1	1	25
	1/0	1/0	1/0	2	2	1/0	1/0	2	2	-	25
	1	1	1	3	3	3	1	1	3	3	25
	2	2	-	4	4	4	2	2	4	4	25
	3	-	-	6	6	6	-	-	6	6	25
WRD279	-	-	4/0	-	3/0	3/0	-	-	-	-	25
	-	3/0	3/0	2/0	2/0	2/0	3/0	3/0	3/0	3/0	25
	2/0	2/0	2/0	1/0	1/0	-	2/0	2/0	2/0	2/0	25
	1/0	4/0	-	1	-	-	1/0	1/0	1/0	1/0	25
	1	-	-	-	-	-	-	-	-	-	25
WRD289	-	-	-	-	-	1/0	-	-	-	-	25
	-	-	-	-	1	1	-	-	1	1	25
	-	-	4/0	2	2	2	3/0	3/0	2	2	25
	-	3/0	3/0	3	3	3	2/0	-	3	3	25
	2/0	2/0	-	4	4	4	-	-	4	4	25
WRD379	1/0	-	-	6	6	6	-	-	6	6	25
	-	-	-	-	-	1/0	-	-	-	-	25
	-	-	-	-	1	1	-	-	1	1	25
	-	-	-	2	2	2	266-18/1	266	2	2	25
	4/0	4/0	-	3	3	3	250	250	3	3	25
WRD399	3/0	-	-	4	4	4	4/0	4/0	4	4	25
	-	-	-	6	6	6	-	-	6	6	25
	-	-	-	-	-	3/0	266-18/1	266	-	-	25
	-	-	-	2/0	2/0	2/0	-	250	-	3/0	25
	4/0	4/0	-	1/0	1/0	-	4/0	4/0	2/0	2/0	25
WRD419	3/0	3/0	-	1	-	-	3/0	-	1/0	1/0	25
	-	-	-	-	-	-	266-18/1	266-18/1	266-18/1	266	25
	4/0	4/0	-	4/0	4/0	-	-	250	-	250	25
	3/0	3/0	-	3/0	3/0	-	4/0	4/0	4/0	4/0	25