

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

YA27  
 7818105031022  
 3/0 CU 1-HOLE LONG 1/2  
 Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Tongue Angle Straight  
 Length (in) 3.06  
 Tongue Type Standard  
 Barrell Style Chamfered  
 Bolt Hole Size (in) 0.52  
 Barrel Type Long  
 Thickness 0.13  
 B Length (in) 1.50  
 Pad Width (in) 0.91  
 Strip Length 1-9/16

**General**

Number of Holes 1  
 Product Description Copper Compression lug, 1 Hole w/o Inspection Window, 3/0 AWG, 1/2" Stud, Long Barrel, Tin Plated

**Conductor(s)**

Flex (Class G) Size - Range N/A  
 Flex (Class H) Size - Range N/A  
 Flex (Class I) Size - Range N/A  
 Copper Solid Size (Range) N/A  
 DLO Size (Range) N/A  
 Copper Stranded (Range) 3/0 AWG

**Physical**

Type of Plating Tin - Electro Plated  
 Bolt Hole Size 1/2  
 Color Code Orange  
 Plated (Yes or No) Y  
 Index Number 14  
 Product Material Copper

**Approvals / Certifications**

UL Listed Y  
 CSA Certified Y  
 ROHS Compatible Compliant  
 UL Recognized N  
 CULUS N  
 Industry Standards UL468A-468B

**Documentation**

For further technical assistance, please contact us


**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175

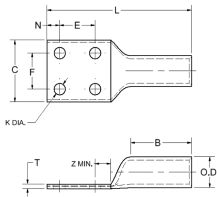

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

YA27  
 7818105031022  
 3/0 CU 1-HOLE LONG 1/2  
 Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Tongue Angle Straight  
 Length (in) 3.06  
 Tongue Type Standard  
 Barrell Style Chamfered  
 Bolt Hole Size (in) 0.52  
 Barrel Type Long  
 Thickness 0.13  
 B Length (in) 1.50  
 Pad Width (in) 0.91  
 Strip Length 1-9/16

**General**

Number of Holes 1  
 Product Description Copper Compression lug, 1 Hole w/o Inspection Window, 3/0 AWG, 1/2" Stud, Long Barrel, Tin Plated

**Conductor(s)**

Flex (Class G) Size - Range N/A  
 Flex (Class H) Size - Range N/A  
 Flex (Class I) Size - Range N/A  
 Copper Solid Size (Range) N/A  
 DLO Size (Range) N/A  
 Copper Stranded (Range) 3/0 AWG

**Physical**

Type of Plating Tin - Electro Plated  
 Bolt Hole Size 1/2  
 Color Code Orange  
 Plated (Yes or No) Y  
 Index Number 14  
 Product Material Copper

**Approvals / Certifications**

UL Listed Y  
 CSA Certified Y  
 ROHS Compatible Compliant  
 UL Recognized N  
 CULUS N  
 Industry Standards UL468A-468B

**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175