

BURNDY Catalog Number YA312LH93TN
UPC Number 7818100857388
Description CUHYSEALUG 350KCMIL TIN PLATED
Status Active

Web Use
 BURNDY Product Line

Dimensional

Tongue Angle Straight
 B Length (Fraction) 1-1/8
 Length (in) 6.00
 Barrell Style Shrouded
 Bolt Hole Size (in) 0.52
 Barrel Type Standard
 Thickness 0.18
 E - in 1.75

General

Number of Holes 2
 Product Description Tin-plated, CU 2-hole NEMA compression terminal with shrouded barrel for terminating insulated CU conductor to transformers and other equipment, 6 IN L

Conductor(s)

Copper Solid Size (Range) N/A
 Copper Stranded (Range) 250 kcmil

Physical

Type of Plating Tin - Electro Plated
 Bolt Hole Size 1/2
 Plated (Yes or No) Y
 Product Material Copper

Approvals / Certifications

UL Listed N
 CSA Certified N
 ROHS Compatible Compliant
 UL Recognized N
 CULUS N


Documentation

For further technical assistance, please contact us

BURNDY LLC - USA
 47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services
 47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

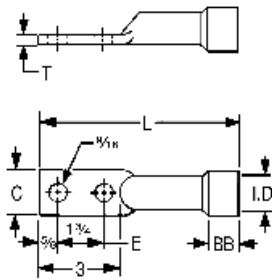

BURNDY Catalog Number YA312LH93TN
UPC Number 7818100857388
Description CUHYSEALUG 350KCMIL TIN PLATED
Status Active

Web Use
 BURNDY Product Line

Dimensional

Tongue Angle Straight
 B Length (Fraction) 1-1/8
 Length (in) 6.00
 Barrell Style Shrouded
 Bolt Hole Size (in) 0.52
 Barrel Type Standard
 Thickness 0.18
 E - in 1.75

General

Number of Holes 2
 Product Description Tin-plated, CU 2-hole NEMA compression terminal with shrouded barrel for terminating insulated CU conductor to transformers and other equipment, 6 IN L

Conductor(s)

Copper Solid Size (Range) N/A
 Copper Stranded (Range) 250 kcmil

Physical

Type of Plating Tin - Electro Plated
 Bolt Hole Size 1/2
 Plated (Yes or No) Y
 Product Material Copper

Approvals / Certifications

UL Listed N
 CSA Certified N
 ROHS Compatible Compliant
 UL Recognized N
 CULUS N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA
 47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services
 47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175